

Appendix

Coding Elements Overview

Metal

Plastic

B-Series

Size D07

Size D15

COM-Series

B-Series

B06


Inserts:

- 1423015, 1423016
- 1407728, 1407727
- 1605611, 1605556
- 1648115, 1648128
- 1648157, 1648160
- 1648024, 1648018
- 1648072, 1648066
- 1648364, 1648351
- 1648380, 1648377





Coding elements:

Plastic: 1686478, 1410916 (HC-BB...)

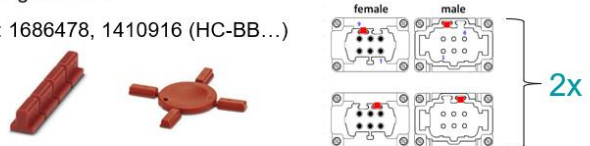

Metal: 1676857, 1676860

 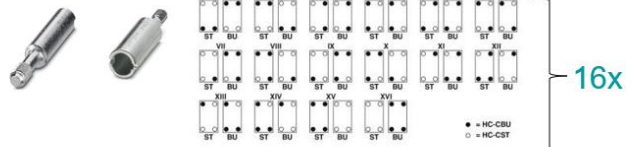

B-Series

B10


Inserts:

- 1014420, 1014419
- 1423017, 1423018
- 1407730, 1407729
- 1407739, 1407743
- 1584059, 1584062
- 1605624, 1605569
- 1636318, 1636321
- 1648173, 1648186
- 1648212, 1648225
- 1584716, 1584729
- 1405260, 1405261
- 1648036, 1648030
- 1648084, 1648078
- 1648403, 1648393
- 1648429, 1648416




Coding elements:

Plastic: 1686478, 1410916 (HC-BB...)

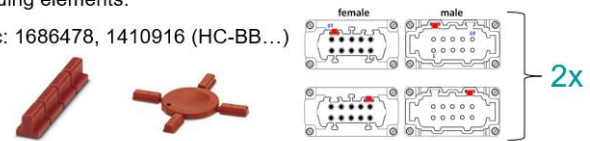

Metal: 1676857, 1676860

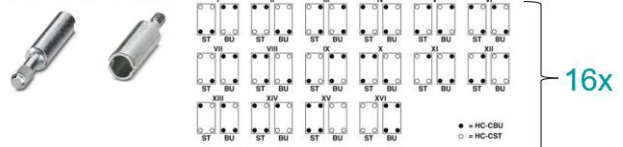

B-Series

B16


▪ Inserts:

1014421, 1014422
1423019, 1423020




▪ Coding elements:

Plastic: 1686478 (), 1410916 (HC-BB...)

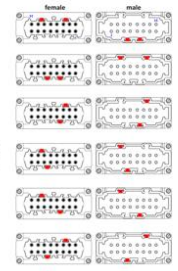


6x

Metal: 1676857, 1676860

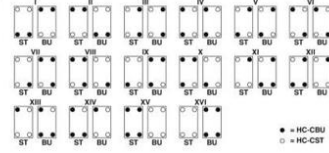

16x

 1772722



6x

B-Series

B24


▪ Inserts:

1014423, 1014424
1423021, 1423022




▪ Coding elements:

Plastic: 1686478, 1410916 (HC-BB...)

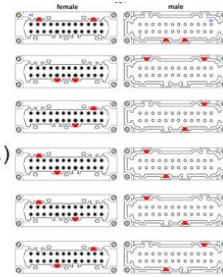


6x

Metal: 1676857, 1676860

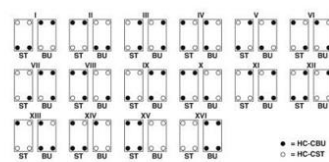

16x

 1772722



6x

Size D07

A03+PE, A04+PE


▪ A03+PE

▪ Inserts:

1585252, 1585265
1585223, 1419896

▪ Coding elements:

1408562

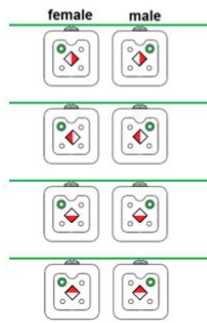

4x


▪ A04+PE

▪ Inserts:

1585278, 1585281
1585236, 1585249

▪ Coding elements:

1408562

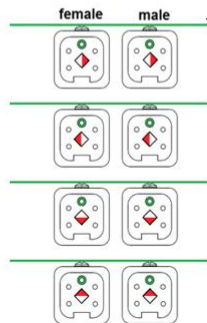

4x


Size D07

D07+PE, D08

▪ D07+PE

▪ Inserts:
1584334, 1584347


▪ Coding elements:
1645888 or 1095422
(sacrifice of one contact)

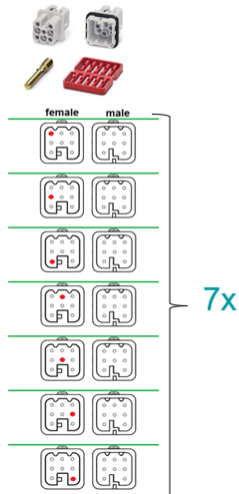

▪ D08

▪ Inserts:
1584350, 1584363

▪ Coding elements:
1645888 or 1095422
(sacrifice of one contact)

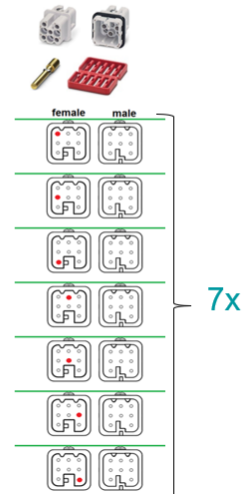


Size D07

HS2+PE, Q02+PE

▪ HS2+PE

▪ Inserts:
1586264, 1586277


▪ Coding elements:
1586280

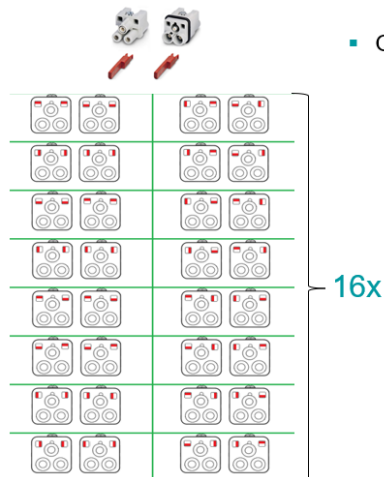

▪ Q2+PE

▪ Inserts:
1419893, 1419895

▪ Coding elements:
1408562

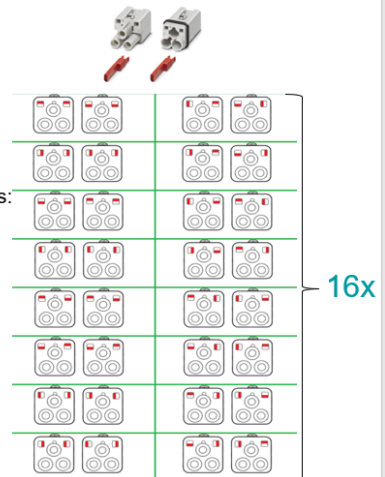


Size D07

Q03+PE, Q04

▪ Q03+PE

▪ Inserts:
1419896, 1419897


▪ Coding elements:
1408562

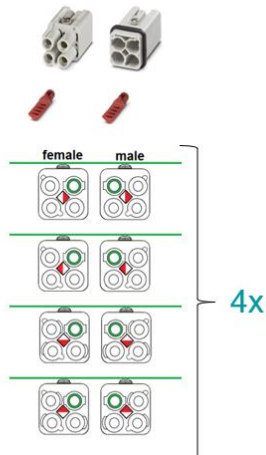

▪ Q4

▪ Inserts:
1419898, 1419899

▪ Coding elements:
1408562

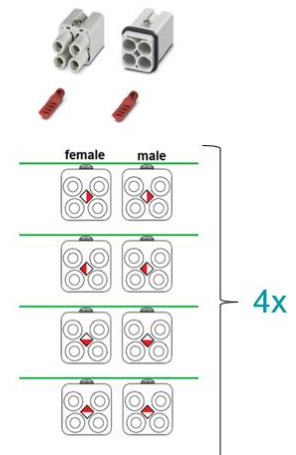


Size D07

Q05+PE, Q07+PE

- Q05+PE

- Inserts:
1406537, 1406538


- Coding elements:
1584693
(sacrifice of one contact)

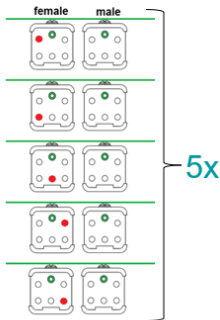

- Q7

- Inserts:
1418623, 1418624

- Coding elements:
1408562

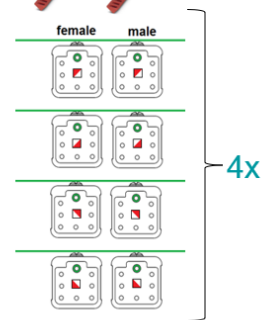

Size D07

Q12+PE

- Q12+PE

- Inserts:
1418626, 1418625

- Coding elements:
1409435



Size D15

A10, A16 (PT, UT)

▪ Inserts:

1585359, 1585362
1585294, 1585304



1585375, 1585388
1585317, 1585320


▪ Coding elements (similar coding to B16):

Plastic: 1410916




6x

Metal: 1676857, 1676860

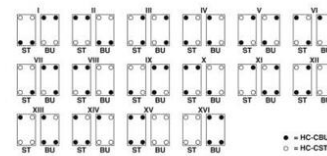

16x

 1772722



6x

Size D15

A10, A16, D15, D25 (Crimp)


▪ A10, A16 Inserts:

1676996, 1676983
1677034, 1677018



▪ Coding elements:

Metal: 1676857, 1676860

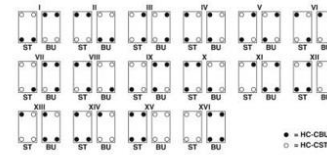

16x

▪ D15, D25 Inserts:

1584376, 1584389
1584392, 1584402



▪ Dummy sockets (under sacrifice of one contact)

1645888 or 1095422

(D15 = 15 positions)
(D25 = 25 positions)

15x



COM-series

COM Q8 & COM 8

▪ COM Q8

▪ Inserts:

1079553, 1079554
1079548, 1079547



▪ COM 8

▪ Inserts:

1408481, 1408494



▪ Coding elements:

1410916



6x

▪ Coding elements:

1584693 (under sacrifice of one contact)



8x

COM-series

COM 17

- Inserts:

1408465, 1408478



- Coding elements:

1645888 or 1095422 (under sacrifice of one contact)

